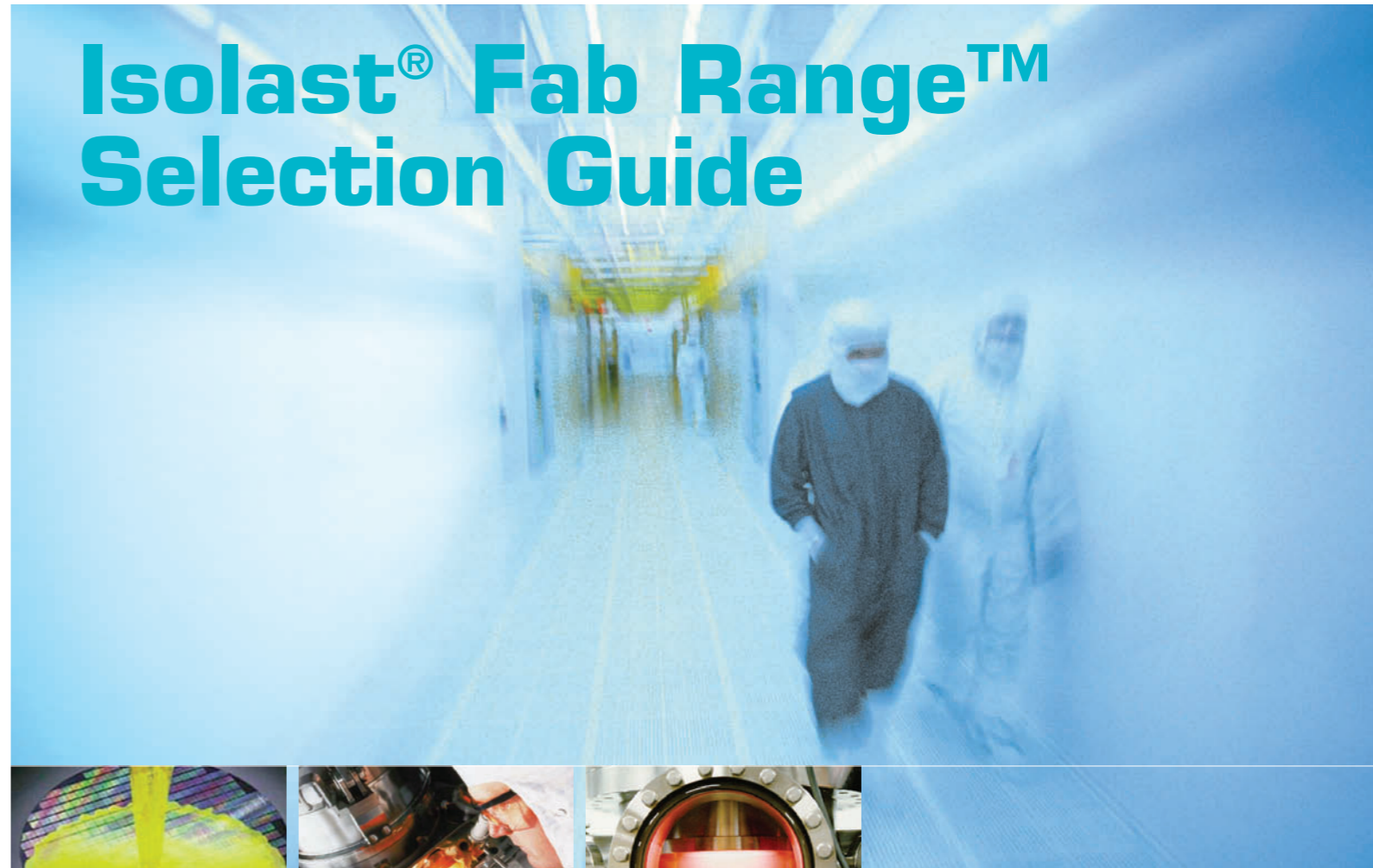


For further information:

Europe	Telephone	America	Telephone
AUSTRIA - Vienna <small>(ALBANIA, BOSNIA AND HERZEGOVINA, CROATIA, HUNGARY, MACEDONIA, SERBIA AND MONTENEGRO, SLOVENIA)</small>	+43 (1) 406 47 33	AMERICAS - Fort Wayne, IN	+1 (260) 749 9631
BELGIUM - Dion-Valmont <small>(LUXEMBOURG)</small>	+32 (10) 22 57 50	BRAZIL - Sao Paulo	+55 (11) 3372 4500
BULGARIA - Sofia <small>(ROMANIA, RUSSIA)</small>	+359 2 96 99 510	CANADA - Ontario	+1 (416) 213 9444
CZECH REPUBLIC - Rakovnik <small>(SLOVAKIA)</small>	+420 313 529 111	MEXICO - Mexico D.F.	+52 55 57 19 50 05
DENMARK - Hillerød	+45 4822 8080	USA, East - Philadelphia, PA	+1 (610) 828 3209
FINLAND - Vantaa <small>(ESTONIA, LATVIA, LITHUANIA)</small>	+358 (0)9 8256 110	USA, Great Lakes - Fort Wayne, IN	+1 (260) 749 6781
FRANCE - Maisons-Laffitte	+33 (0)1 30 86 56 00	USA, Midwest - Lombard, IL	+1 (630) 268 9915
GERMANY - Stuttgart	+49 (711) 7 86 40	USA, Mountain - Broomfield, CO	+1 (303) 469 1357
GREECE	+41 (21) 6314111	USA, Northern California - Fresno, CA	+1 (559) 449 6070
ITALY - Livorno	+39 (0586) 22 61 11	USA, Northwest - Portland, OR	+1 (503) 595 6565
THE NETHERLANDS - Barendrecht	+31 (10) 29 22 111	USA, South - N. Charleston, SC	+1 (843) 747 7656
NORWAY - Oslo	+47 22 64 60 80	USA, Southwest - Houston, TX	+1 (713) 461 3495
POLAND - Warsaw <small>(BELARUS, LITHUANIA, UKRAINE)</small>	+48 (22) 8 63 30 11	USA, West - Torrance, CA	+1 (310) 371 1025
RUSSIA - Moscow	+7 495 982 39 21		
SPAIN - Madrid <small>(PORTUGAL)</small>	+34 91 710 5730	Asia	Telephone
SWEDEN - Jönköping	+46 (36) 34 15 00	ASIA PACIFIC REGIONAL	+65 (6)265 6883
SWITZERLAND - Crissier	+41 (21) 631 41 11	CHINA - Hong Kong	+852 (2)366 9165
TURKEY	+41 (21) 631 41 11	INDIA - Bangalore	+91 (80) 2655 5157
UNITED KINGDOM - Solihull <small>(EIRE)</small>	+44 (0)121 744 1221	JAPAN - Tokyo	+81 (3) 5633 8008
AFRICA REGIONAL	+41 (21) 631 41 11	KOREA - Gyunggi-Do	+82 (31) 386 3283
MIDDLE EAST REGIONAL	+41 (21) 631 41 11	MALAYSIA - Kuala Lumpur	+60 (0) 3 9059 6388
		TAIWAN - Taichung	+886 (4) 23 58 00 82
		THAILAND - Bangkok	+66 (0) 2732-2861
		SINGAPORE	
		and all other countries in Asia	+65 (6)293 2500

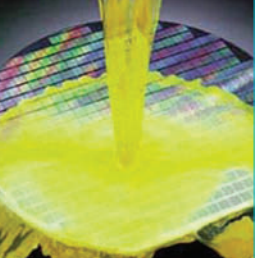

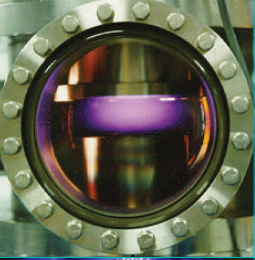
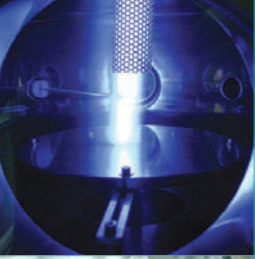
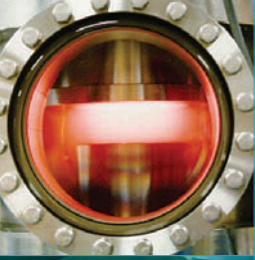
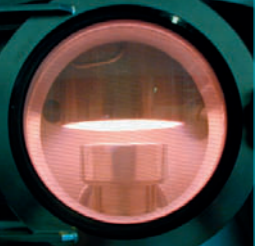
Semicon Segment Contacts:
Americas + 925 858 1394
Asia + 886 930982646
Europe +49 1727446176

www.tss.trelleborg.com



Your Partner for Sealing Technology

Range of ultra pure sealing perfluorelastomers specifically for semiconductor and nanotechnology industries

Application	Compound	Processes	Typical Chemicals/Gases	Operating Temperature	Hardness shore A, IRHD +/- 5	Color	Compression Set in % ASTM D 395B 72 h/204 °C/400 °F
	J9610	wet cleaning etching stripping plating CMP	TMAH, Stoddard Solvent, HF, H ₃ PO ₄ , nMP, CuSO ₄ , UPDI, CMP slurries	-25 °C / 235 °C -13 °F / 455 °F	75	black	17
	J9650	RTP, CVD diffusion dry plasma etch, dry ashing metallization deposition annealing	Resistance to IR absorption, SF ₆ , CF ₄ /O ₂ , NF ₃ , O ₂ , CHF ₃ , TMS, TEOS, SiH ₄ , High Vacuum	-15 °C / 320 °C 5 °F / 608 °F	75	black	14
	J9630	dry plasma etch oxidation CVD plasma ashing diffusion metallization	SF ₆ , CF ₄ /O ₂ , NF ₃ , O ₂ , NH ₃ , CHF ₃ , TMS, TEOS, SiH ₄	-15 °C / 260 °C 5 °F / 500 °F	85	white	30
	J9670	high temperature plasma processes dry plasma etch PVD, CVD	SF ₆ , BCl ₃ /O ₂ , NF ₃ , CHF ₃ , O ₂ , HCl, High Vacuum, Al, Cu, Ta, Ti, TEP, TEOS, SiH ₄	-15 °C / 315 °C 5 °F / 599 °F	75	beige	30
	J9680	dry plasma etch oxidation CVD plasma ashing diffusion metallization	SF ₆ , BCl ₃ /O ₂ , CHF ₃ , O ₂ , HCl, Al, Cu, Ta, Ti, TEP, TEOS, SiH ₄	-10 °C / 230 °C 14 °F / 446 °F	75	translucent	30
	J9675	ECP wet stripping fluorine + oxygen based plasma processes	ArF ₂ , NF ₃ , CuSO ₄ , H ₂ SO ₄ , nMP, Hydroxylamine, O ₂ , CF ₄ , SF ₆ , CCl ₄ , Cl ₂	-15 °C / 300 °C 5 °F / 572 °F	75	cream	20

Available on O-rings, square and special section seals, V-rings®, as well as custom molded seals and engineered solutions.